

Technical data sheet

Counter-trough, metal universal, DD

Item number: 1199854



Metal counter-trough, for mounting on clamp clip. Can be used universally, irrespective of the rail.



- St

Steel
- DD

Strip galvanised zinc/aluminium, Double Dip

Master data	
Item number	1199854
Type	2058FW M 16 DD
Description 1	Counter-trough
Manufacturer	OBO
Dimension	12-16mm
Material	Steel
Surface	Strip galvanised zinc/aluminium, Double Dip
Surface standard	DIN EN 10346
Smallest sales unit	100
Unit of quantity	Piece
Weight	1.1 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0292 kg COe / 1 Piece

Technical data sheet

Counter-trough, metal universal, DD


Item number: 1199854



Dimensions



Dimension B	21.5 mm
Dimension H	7.7 mm
Dimension L	35 mm

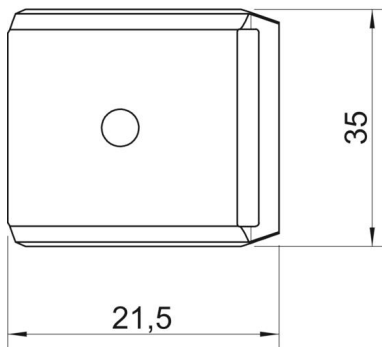

Technical data

Counter-trough/clip version	Counter sleeve
Suitable for max. cable diameter	16 mm
Halogen-free	yes
Clamping range D, max.	16 mm
Clamping range D, min.	12 mm