

Technical data sheet

Counter-trough, metal, universal A2

Item number: 1197290



Metal counter-trough, for mounting on clamp clip. Can be used universally, irrespective of the rail.



- A2Stainless steel
- 2BBright, treated

| Master data                       |                         |
|-----------------------------------|-------------------------|
| Item number                       | 1197290                 |
| Type                              | 2058FW M 28 A2          |
| Description 1                     | Counter-trough          |
| Manufacturer                      | OBO                     |
| Dimension                         | 22-28mm                 |
| Material                          | Stainless steel         |
| Surface                           | Bright, treated         |
| Surface standard                  |                         |
| Smallest sales unit               | 100                     |
| Unit of quantity                  | Piece                   |
| Weight                            | 1.356 kg                |
| Weight unit                       | kg/100 pc.              |
| CO Footprint (GWP) Cradle-to-Gate | 0,0841 kg COe / 1 Piece |

# Technical data sheet

## Counter-trough, metal, universal A2


Item number: 1197290



### Dimensions



|             |         |
|-------------|---------|
| Dimension B | 34 mm   |
| Dimension H | 10.4 mm |
| Dimension L | 35 mm   |

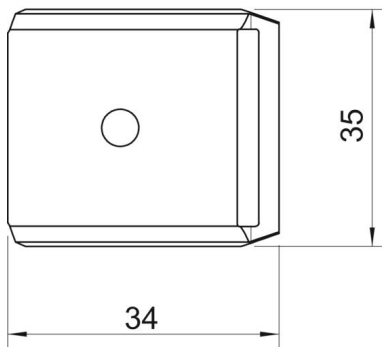

### Technical data

|                                  |                |
|----------------------------------|----------------|
| Counter-trough/clip version      | Counter sleeve |
| Suitable for max. cable diameter | 28 mm          |
| Halogen-free                     | yes            |
| Clamping range D, max.           | 28 mm          |
| Clamping range D, min.           | 22 mm          |