

Technical data sheet

Counter-trough, metal, universal A2

Item number: 1197592



Metal counter-trough, for mounting on clamp clip. Can be used universally, irrespective of the rail.

CE

F

N

H

U

W

A2

Stainless steel

2B

Bright, treated

| Master data                       |                       |
|-----------------------------------|-----------------------|
| Item number                       | 1197592               |
| Description 1                     | Counter-trough        |
| Manufacturer                      | OBO                   |
| Dimension                         | 52-58mm               |
| Material                          | Stainless steel       |
| Surface                           | Bright, treated       |
| Surface standard                  |                       |
| Smallest sales unit               | 50                    |
| Unit of quantity                  | Piece                 |
| Weight                            | 3.776 kg              |
| Weight unit                       | kg/100 pc.            |
| CO Footprint (GWP) Cradle-to-Gate | 0,27 kg COe / 1 Piece |

# Technical data sheet

## Counter-trough, metal, universal A2


Item number: 1197592



### Dimensions



|             |         |
|-------------|---------|
| Dimension B | 40 mm   |
| Dimension H | 13.5 mm |
| Dimension L | 35 mm   |

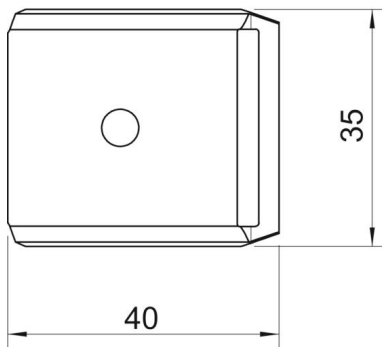

### Technical data

|                                  |                |
|----------------------------------|----------------|
| Counter-trough/clip version      | Counter sleeve |
| Suitable for max. cable diameter | 58 mm          |
| Halogen-free                     | yes            |
| Clamping range D, max.           | 58 mm          |
| Clamping range D, min.           | 52 mm          |