

Technical data sheet

Counter-trough, metal universal, DD

Item number: 1199927



Metal counter-trough, for mounting on clamp clip. Can be used universally, irrespective of the rail.



- St

Steel
- DD

Strip galvanised zinc/aluminium, Double Dip

Master data

Item number	1199927
Type	2058FW M 58 DD
Description 1	Counter-trough
Manufacturer	OBO
Dimension	52-58mm
Material	Steel
Surface	Strip galvanised zinc/aluminium, Double Dip
Surface standard	DIN EN 10346
Smallest sales unit	50
Unit of quantity	Piece
Weight	3.62 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,1029 kg COe / 1 Piece

Technical data sheet

Counter-trough, metal universal, DD


Item number: 1199927



Dimensions



Dimension B	64 mm
Dimension H	20.3 mm
Dimension L	35 mm

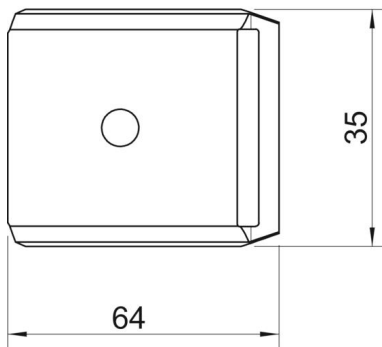

Technical data

Counter-trough/clip version	Counter sleeve
Suitable for max. cable diameter	58 mm
Halogen-free	yes
Clamping range D, max.	58 mm
Clamping range D, min.	52 mm