

Technical data sheet

Counter-trough, metal, universal A2

Item number: 1197606



Metal counter-trough, for mounting on clamp clip. Can be used universally, irrespective of the rail.



A2 Stainless steel

2B Bright, treated

Master data

Item number	1197606
Type	2058FW M 64 A2
Description 1	Counter-trough
Manufacturer	OBO
Dimension	58-64mm
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	50
Unit of quantity	Piece
Weight	4.203 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,2901 kg COe / 1 Piece

Technical data sheet

Counter-trough, metal, universal A2


Item number: 1197606



Dimensions



Dimension B	70 mm
Dimension H	24.5 mm
Dimension L	35 mm

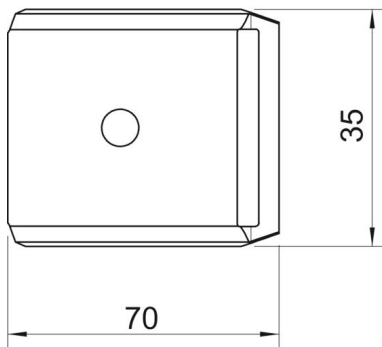

Technical data

Counter-trough/clip version	Counter sleeve
Suitable for max. cable diameter	64 mm
Halogen-free	yes
Clamping range D, max.	64 mm
Clamping range D, min.	58 mm