

Technical data sheet

Long trough

Item number: 1195840



In addition to the clamp clip, to increase the support area for cables with integrated maintenance of electrical function, a long trough (L = 200 mm) is mounted.




St	Steel
FS	Strip galvanized

Master data

Item number	1195840
Type	2058 LW 38
Description 1	Long trough
Description 2	for clamp clip 34-40 mm
Manufacturer	OBO
Dimension	32-38, 200mm
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	25
Unit of quantity	Piece
Weight	12.5 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,307 kg COe / 1 Piece

Dimensions

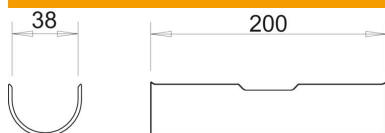

Technical data sheet

Long trough

Item number: 1195840



Technical data

Counter-trough/clip version	Long trough
Clamping range D, max.	38 mm
Clamping range D, min.	32 mm
for clip 2056/M, max.	40
for clip 2056/M, min.	34 mm