

Technical data sheet

Double trough, metal DD

Item number: 1199706



Metallic double trough as intermediate layer between two or three cables within a clamp clip.



- St** Steel
- DD** Strip galvanised zinc/aluminium, Double Dip

Master data		
Item number	1199706	
Type	2058 M2 12 DD	
Description 1	Double trough	
Manufacturer	OBO	
Dimension	8-12mm	
Material	Steel	
Surface	Strip galvanised zinc/aluminium, Double Dip	
Surface standard	DIN EN 10346	
Smallest sales unit	100	
Unit of quantity	Piece	
Weight	1.36 kg	
Weight unit	kg/100 pc.	
CO Footprint (GWP) Cradle-to-Gate	0,0453 kg COe / 1 Piece	


Technical data sheet

Double trough, metal DD


Item number: 1199706



Dimensions

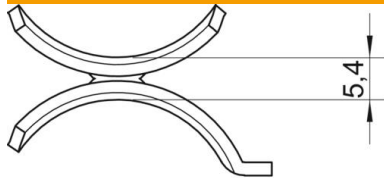

Dimension B	17.6 mm
Dimension H	5.4 mm
Dimension L	35 mm

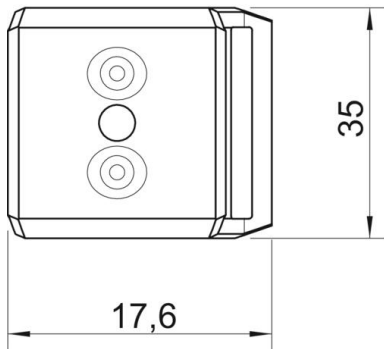

Technical data

Counter-trough/clip version	Double trough
Suitable for max. cable diameter	12 mm
Clamping range D, max.	12 mm
Clamping range D, min.	8 mm