

Technical data sheet

Double trough, metal DD

Item number: 1199722



Metallic double trough as intermediate layer between two or three cables within a clamp clip.



St

Steel

DD

Strip galvanised zinc/aluminium, Double Dip

Master data		
Item number	1199722	
Type	2058 M2 22 DD	
Description 1	Double trough	
Manufacturer	OBO	
Dimension	16-22mm	
Material	Steel	
Surface	Strip galvanised zinc/aluminium, Double Dip	
Surface standard	DIN EN 10346	
Smallest sales unit	50	
Unit of quantity	Piece	
Weight	2.3 kg	
Weight unit	kg/100 pc.	
CO Footprint (GWP) Cradle-to-Gate	0,0621 kg COe / 1 Piece	


Technical data sheet

Double trough, metal DD


Item number: 1199722



Dimensions

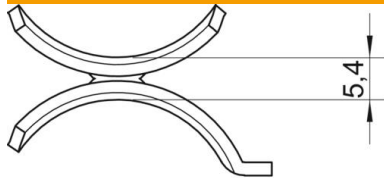

Dimension B	28 mm
Dimension H	5.4 mm
Dimension L	35 mm

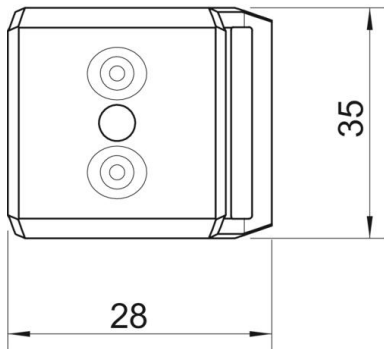

Technical data

Counter-trough/clip version	Double trough
Suitable for max. cable diameter	22 mm
Clamping range D, max.	22 mm
Clamping range D, min.	16 mm