

Technical data sheet

Double trough, metal A2

Item number: 1196599



Metallic double trough as intermediate layer between two or three cables within a clamp clip.



A2	Stainless steel
2B	Bright, treated

Master data		
Item number	1196599	
Type	2058 M2 28 A2	
Description 1	Double trough	
Manufacturer	OBO	
Dimension	22-28mm	
Material	Stainless steel	
Surface	Bright, treated	
Surface standard		
Smallest sales unit	50	
Unit of quantity	Piece	
Weight	3.1 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,2062 kg COe / 1 Piece	


Technical data sheet

Double trough, metal A2


Item number: 1196599



Dimensions

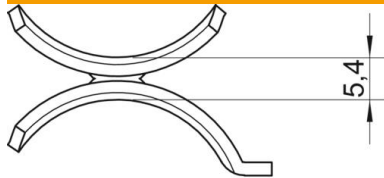

Dimension B	34 mm
Dimension H	5.4 mm
Dimension L	35 mm

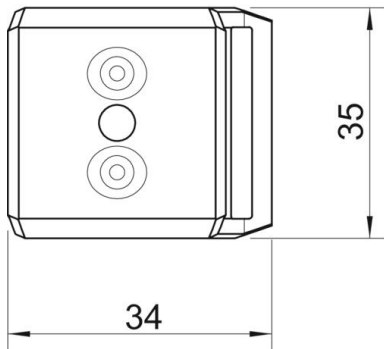

Technical data

Counter-trough/clip version	Double trough
Suitable for max. cable diameter	28 mm
Clamping range D, max.	28 mm
Clamping range D, min.	22 mm