


Technical data sheet

Hat profile rail, perforated GTP

Item number: 1115596

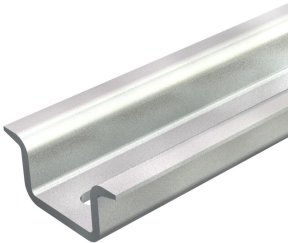

Hat profile rail 35 x 15 mm to DIN EN 60715 (formerly DIN EN 50022).



- St

Steel
- GTP

Electrogalvanized, transparently passivated

Master data	
Item number	1115596
Type	2069 15 2.2 GTPL
Description 1	Top hat rail
Description 2	perforated, 2.25 mm thick
Manufacturer	OBO
Dimension	2000x35x15
Material	Steel
Surface	Electrogalvanized, transparently passivated
Surface standard	
Smallest sales unit	2
Unit of quantity	Metre
Weight	97 kg
Weight unit	kg/100 m
CO Footprint (GWP) Cradle-to-Gate	1,6517 kg COe / 1 Meter


Technical data sheet

Hat profile rail, perforated GTP

Item number: 1115596



Dimensions

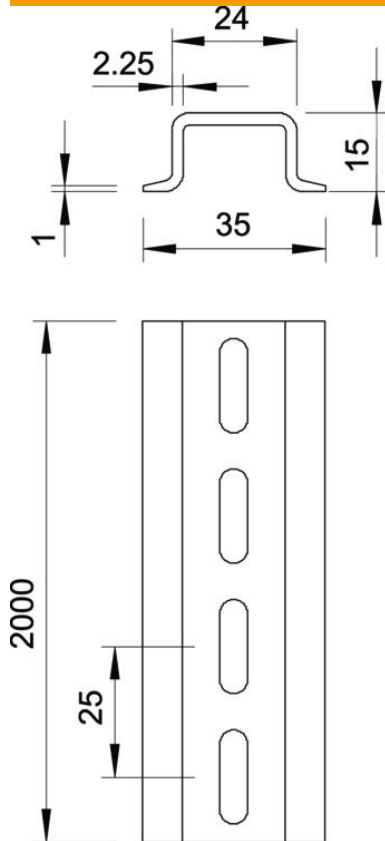

Length	2,000 mm
Width	35 mm
Height	15 mm

Technical data

Version for	Perforated
Version, rails	Support rail DIN EN 60715
Drill hole spacing, centre	25 mm
Bundle	20 m
Hole shape (ETIM)	Long slot
Material thickness	2.25 mm