

Technical data sheet

Hat profile rail, unperforated GTP

Item number: 1115685



Hat profile rail 35 x 7.5 mm to DIN EN 60715 (formerly DIN EN 50022).



- StSteel
- GTPElectrogalvanized, transparently passivated

Master data	
Item number	1115685
Type	2069 1M GTP
Description 1	Top hat rail
Description 2	unperforated
Manufacturer	OBO
Dimension	1000x35x7,5
Material	Steel
Surface	Electrogalvanized, transparently passivated
Surface standard	
Smallest sales unit	25
Unit of quantity	Metre
Weight	36.02 kg
Weight unit	kg/100 m
CO Footprint (GWP) Cradle-to-Gate	0,6227 kg COe / 1 Meter


Technical data sheet

Hat profile rail, unperforated GTP


Item number: 1115685



Dimensions

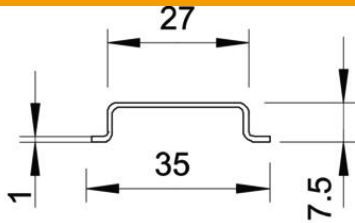

Length	1,000 mm
Width	35 mm
Height	7.5 mm

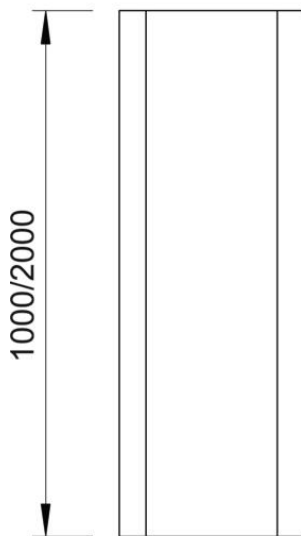

Technical data

Version for	Unperforated
Version, rails	Support rail DIN EN 60715
Bundle	25 m
Hole shape (ETIM)	Without
Material thickness	1 mm