


# Technical data sheet

Cover for WDK trunking, trunking width 150 mm

Item number: 6022731

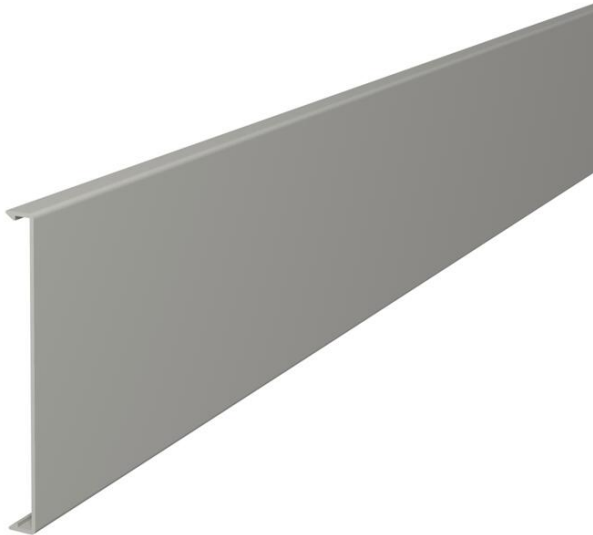

Cover for closing the trunking.



**PVC** Polyvinylchloride

| Master data                        |                          |
|------------------------------------|--------------------------|
| Item number                        | 6022731                  |
| Type                               | 2410 150GR               |
| Description 1                      | Cover                    |
| Description 2                      | for WDK                  |
| Manufacturer                       | OBO                      |
| Dimension                          | 150x2000mm               |
| Colour                             | Stone grey; RAL 7030     |
| Material                           | Polyvinylchloride        |
| Smallest sales unit                | 2                        |
| Unit of quantity                   | Metre                    |
| Weight                             | 54 kg                    |
| Weight unit                        | kg/100 m                 |
| CO2 Footprint (GWP) Cradle-to-Gate | 1,1607 kg CO2e / 1 Meter |


# Technical data sheet

Cover for WDK trunking, trunking width 150 mm

Item number: 6022731



## Dimensions

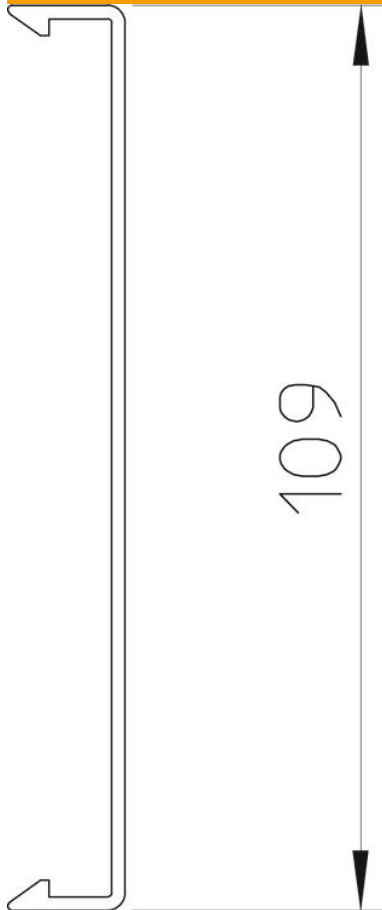

|        |          |
|--------|----------|
| Length | 2,000 mm |
| Width  | 150 mm   |

## Technical data

|                                   |       |
|-----------------------------------|-------|
| Maintain electrical functions     | no    |
| Halogen-free                      | no    |
| Protection rating                 | IP30  |
| Protection rating IK code         | IK04  |
| Permitted temperature range, max. | 60 °C |
| Permitted temperature range, min. | -5 °C |