

Technical data sheet

Cover for WDK trunking, trunking width 210 mm

Item number: 6022774



Cover for closing the trunking.



PVC Polyvinylchloride

Master data	
Item number	6022774
Type	2410 210GR
Description 1	Cover
Description 2	for WDK
Manufacturer	OBO
Dimension	210x2000mm
Colour	Stone grey; RAL 7030
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Metre
Weight	72.2 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	1,4138 kg CO2e / 1 Meter


Technical data sheet

Cover for WDK trunking, trunking width 210 mm

Item number: 6022774



Dimensions

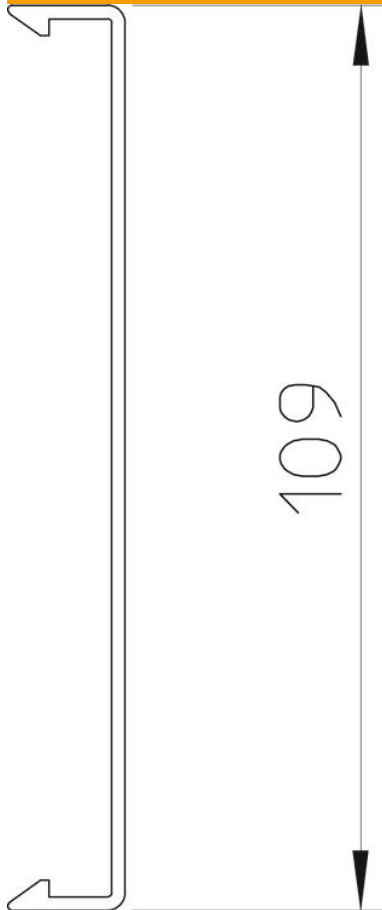

Length	2,000 mm
Width	210 mm

Technical data

Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C