

# Technical data sheet

Cover for WDK trunking, trunking width 40 mm

Item number: 6027601



Cover for closing the trunking.



**PVC** Polyvinylchloride

## Master data

|                                    |                         |
|------------------------------------|-------------------------|
| Item number                        | 6027601                 |
| Type                               | 2410 40CW               |
| Description 1                      | Cover                   |
| Description 2                      | for WDK                 |
| Manufacturer                       | OBO                     |
| Dimension                          | 40x2000mm               |
| Colour                             | Cream; RAL 9001         |
| Material                           | Polyvinylchloride       |
| Smallest sales unit                | 2                       |
| Unit of quantity                   | Metre                   |
| Weight                             | 11.3 kg                 |
| Weight unit                        | kg/100 m                |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,214 kg CO2e / 1 Meter |


# Technical data sheet

Cover for WDK trunking, trunking width 40 mm

Item number: 6027601



## Dimensions

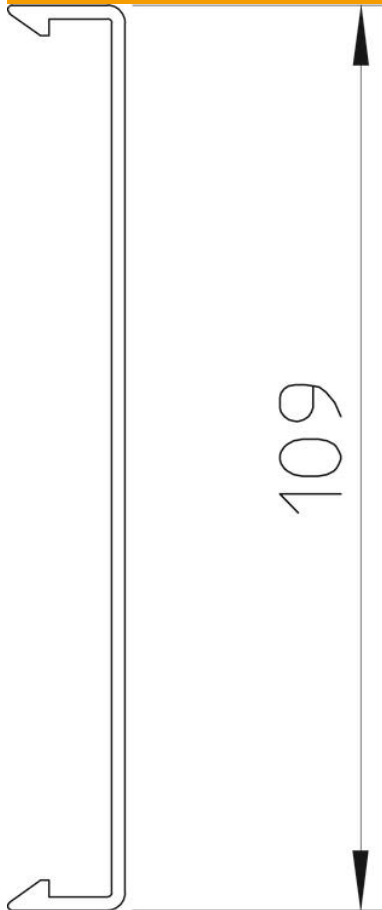

|        |          |
|--------|----------|
| Length | 2,000 mm |
| Width  | 40 mm    |

## Technical data

|                                   |       |
|-----------------------------------|-------|
| Maintain electrical functions     | no    |
| Halogen-free                      | no    |
| Protection rating                 | IP30  |
| Protection rating IK code         | IK04  |
| Permitted temperature range, max. | 60 °C |
| Permitted temperature range, min. | -5 °C |