

Technical data sheet

Cover for WDK trunking, trunking width 40 mm

Item number: 6191568



Cover for closing the trunking.



PVC Polyvinylchloride

Master data

Item number	6191568
Type	2410 40RW
Description 1	Cover
Description 2	for WDK
Manufacturer	OBO
Dimension	40x2000mm
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Metre
Weight	11.3 kg
Weight unit	kg/100 m


Technical data sheet

Cover for WDK trunking, trunking width 40 mm

Item number: 6191568



Dimensions

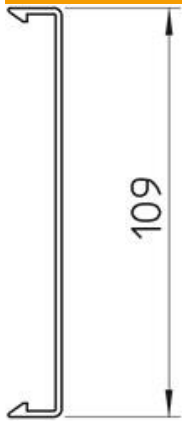

Length	2,000 mm
Width	40 mm

Technical data

Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C