

Technical data sheet

Cover for WDK trunking, trunking width 60 mm

Item number: 6022685



Cover for closing the trunking.



PVC Polyvinylchloride

Master data	
Item number	6022685
Type	2410 60GR
Description 1	Cover
Description 2	for WDK
Manufacturer	OBO
Dimension	60x2000mm
Colour	Stone grey; RAL 7030
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Metre
Weight	15.4 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,3673 kg CO2e / 1 Meter


Technical data sheet

Cover for WDK trunking, trunking width 60 mm

Item number: 6022685



Dimensions

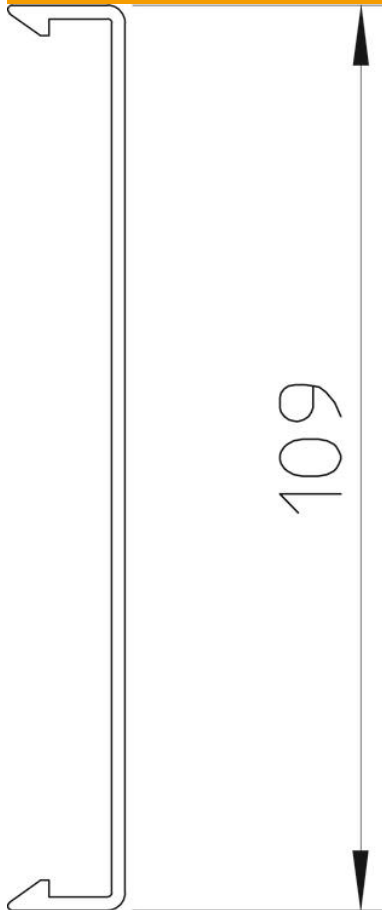

Length	2,000 mm
Width	60 mm

Technical data

Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C