

Technical data sheet

Cover for WDK trunking, trunking width 90 mm

Item number: 6022707



Cover for closing the trunking.



PVC Polyvinylchloride

Master data

Item number	6022707
Type	2410 90GR
Description 1	Cover
Description 2	for WDK
Manufacturer	OBO
Dimension	90x2000mm
Colour	Stone grey; RAL 7030
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Metre
Weight	26.5 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,5992 kg CO2e / 1 Meter


Technical data sheet

Cover for WDK trunking, trunking width 90 mm

Item number: 6022707



Dimensions

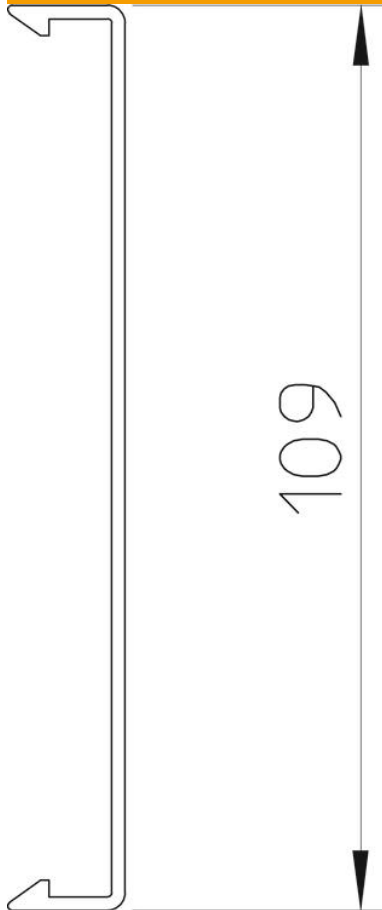

Length	2,000 mm
Width	90 mm

Technical data

Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C