


Technical data sheet

T connector Rd 8–10 mm FT

Item number: 5311101



- With 2 hexagonal bolts M6 x 16 (VA)
- Complies with the requirements of VDE 0185-305-3 (IEC/ EN 62305-3)

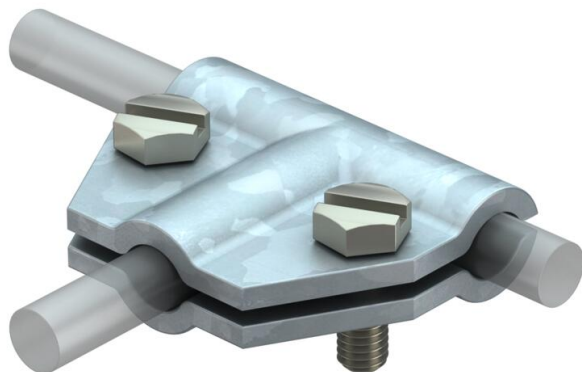

St

Steel

FT

Hot-dip galvanised

Master data

Item number	5311101
Type	245 8-10 FT
Description 1	T-connector
Manufacturer	OBO
Dimension	8-10mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	10
Unit of quantity	Piece
Weight	9.401 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2506 kg CO2e / 1 Piece


Technical data sheet

T connector Rd 8–10 mm FT

Item number: 5311101



Dimensions

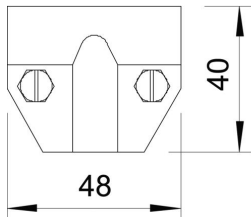

Technical data

Type of fastening screw	Hexagonal bolt
Type of connector	T connector
Lightning current carrying capacity	N/50 kA
Suitable for connection	Round conductor Rd 8–10 / Rd 8–10
Fit	Rd 8-10 mm
Intermediate plate	no