


# Technical data sheet

## T connector Rd 8-10 mm, triple-screwed FT

Item number: 5311209



- With 3 hexagonal bolts M6 x 16 (VA)

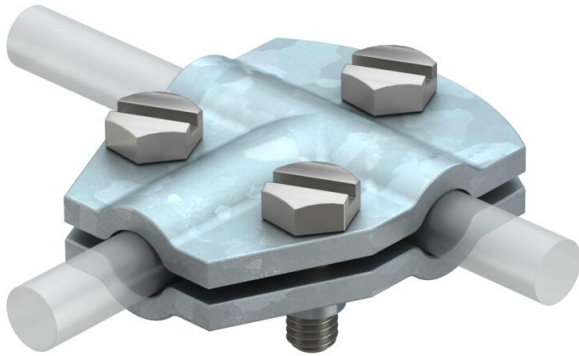

St	Steel
FT	Hot-dip galvanised

### Master data

Item number	5311209
Type	247 8-10 FT
Description 1	T-connector
Manufacturer	OBO
Dimension	8-10mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	10
Unit of quantity	Piece
Weight	10.934 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,3008 kg CO2e / 1 Piece


# Technical data sheet

T connector Rd 8-10 mm, triple-screwed FT

Item number: 5311209



## Dimensions

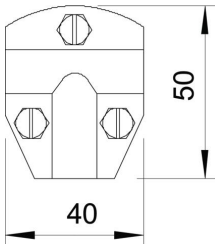

## Technical data

Type of fastening screw	Hexagonal bolt
Type of connector	T connector
Lightning current carrying capacity	N/50 kA
Suitable for connection	Round conductor Rd 8–10 / Rd 8–10
Fit	Rd 8-10 mm
Intermediate plate	no