


# Technical data sheet

## Diagonal clamp for flat conductors and round conductors A2

Item number: 5313023

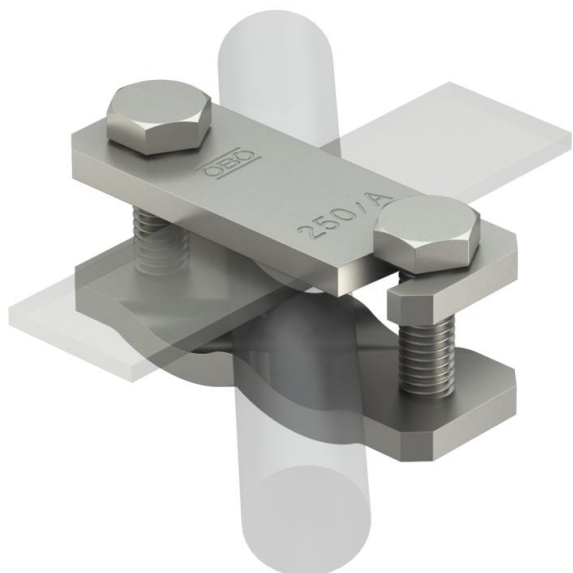

- For reinforced steels Ø 6–22 mm and flat conductors 50 x 4
- Mounted with bolts M10 x 40
- Simple mounting through open slot



**A2** Stainless steel

### Master data

|                     |                 |
|---------------------|-----------------|
| Item number         | 5313023         |
| Description 1       | Diagonal clamp  |
| Manufacturer        | OBO             |
| Dimension           | 88x30x45        |
| Material            | Stainless steel |
| Smallest sales unit | 10              |
| Unit of quantity    | Piece           |
| Weight              | 21.2 kg         |
| Weight unit         | kg/100 pc.      |


# Technical data sheet

## Diagonal clamp for flat conductors and round conductors A2


Item number: 5313023



### Dimensions

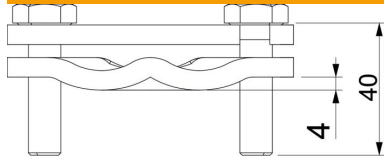

|             |       |
|-------------|-------|
| Dimension A | 30 mm |
| Dimension B | 88 mm |
| Dimension L | 40 mm |

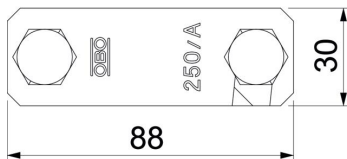

### Technical data

|                                             |                      |
|---------------------------------------------|----------------------|
| Type of fastening screw                     | Hexagonal bolt       |
| Type of connector                           | Connectors           |
| Lightning current carrying capacity         | H/100 kA             |
| Flat conductor width, conductor 2, max.     | 50                   |
| Flat conductor width, conductor 2, min.     | 0                    |
| Suitable for connection                     | Miscellaneous        |
| Fit                                         | Rd 6-22/max. FL50 mm |
| Round conductor diameter, conductor 1, max. | 22 mm                |
| Round conductor diameter, conductor 1, min. | 6 mm                 |
| Intermediate plate                          | no                   |