


Technical data sheet

Cross-connector flat/flat without adapter plate FT

Item number: 5314572

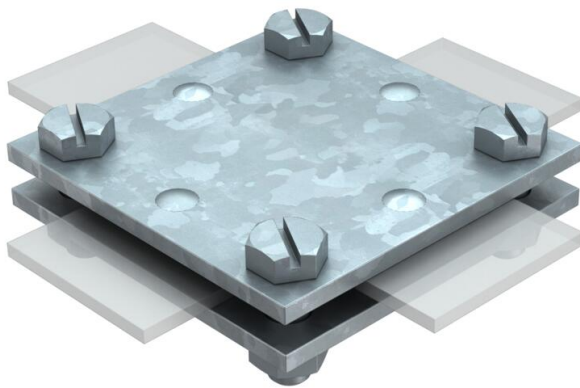

- Meets the requirements of VDE 0185-305-3 (IEC/EN 62305-3)
- Fit: Max. FL 30 x FL 30 or max. FL 40 x FL 40
- Without adapter plate
- Mounted with 4 hexagonal bolts M8 x 25 and 4 hexagonal nuts M8 (F)



St

Steel

FT

Hot-dip galvanised

Master data

Item number	5314572
Type	256 S6 FT
Description 1	Cross-connectors flat/flat
Description 2	no intermediate plate
Manufacturer	OBO
Dimension	30mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	3600
Unit of quantity	Piece
Weight	22.4 kg
Weight unit	kg/100 pc.

Technical data sheet

Cross-connector flat/flat without adapter plate FT


Item number: 5314572



Dimensions



Dimension A	60 mm
Dimension B	60 mm

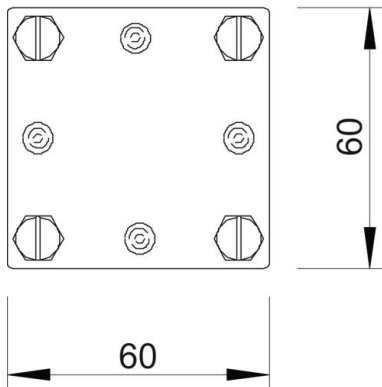

Technical data

Type of fastening screw	Hexagonal bolt
Type of connector	Cross-connectors
Lightning current carrying capacity	H/100 kA
Suitable for connection	Flat conductor FI 30 / FI 30
Fit	max. FL30 mm