


Technical data sheet

Folding clamp and connection terminal up to 5 mm Cu plate thickness

Item number: 5317479



- Plate thickness to 5 mm
- For cable routing along and across the plate
- 4 hexagonal bolts M6 x 16
- Meets the requirements of VDE 0185-305 (IEC 62305)

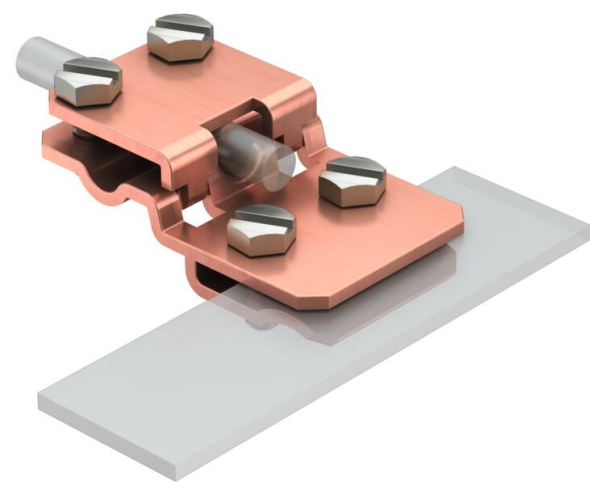

Cu Copper

Master data		
Item number	5317479	
Type	274 CU	
Description 1	Folding clamp	
Manufacturer	OBO	
Dimension	8mm	
Material	Copper	
Smallest sales unit	10	
Unit of quantity	Piece	
Weight	11.34 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,4992 kg CO2e / 1 Piece	


Technical data sheet

Folding clamp and connection terminal up to 5 mm Cu plate thickness

Item number: 5317479



Dimensions

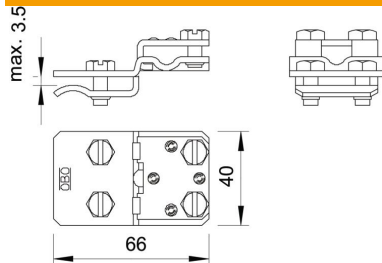

Technical data

Type of fastening screw	Hexagonal bolt
Type of connector	Folding clamp
Lightning current carrying capacity	N/50 kA
Fit	Rd 8 mm
Clamping range, max.	5 mm