


Technical data sheet

Screw-in spacer clip, heavy-duty version M8

Item number: 1387170

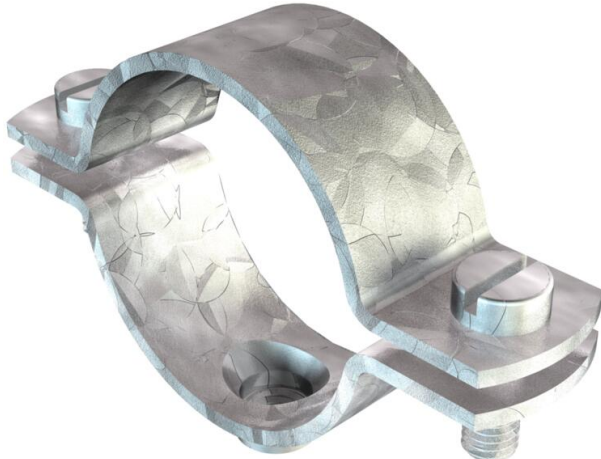

Can be screwed onto M8 thread. Size 27 FT is suitable for M25. Size 42.5 FT is suitable for M40. Size 48.5 FT is suitable for M50. Size 60 FT is suitable for M63.



St

Steel

FT

Hot-dip galvanised

Master data

Item number	1387170
Type	2900WM8 88 FT
Description 1	Distance saddle
Description 2	with threaded connection M8
Manufacturer	OBO
Dimension	3"
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	50
Unit of quantity	Piece
Weight	23.8 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,4973 kg COe / 1 Piece


Technical data sheet

Screw-in spacer clip, heavy-duty version M8

Item number: 1387170



Dimensions

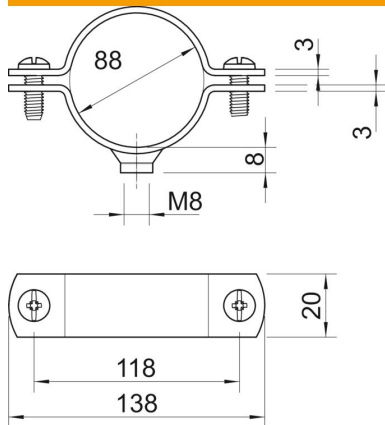

Length	138 mm
Width	20 mm
Dimension A	138 mm
Dimension B	118 mm
Dimension D	88 mm
Dimension d min.	88 mm
Dimension t	3 mm
Dimension t1 (mm)	3
Dimension x	5 mm

Technical data

Version for	Closed
Fastening type	Screw hole
For diameter	88
for pipe diameter	M95
Suitable in fire protection area	no
Thread	M8
Size	3"
Halogen-free	no
Plastic-covered	no
Hole size	M8 mm
Material thickness	3 mm
Bolt	M6 x 18
Clamping range D, max.	88 mm
Clamping range D, min.	83 mm
UV-resistant	yes