


Technical data sheet

Screw-in spacer clip, universal

Item number: 1383299



With M6 thread.

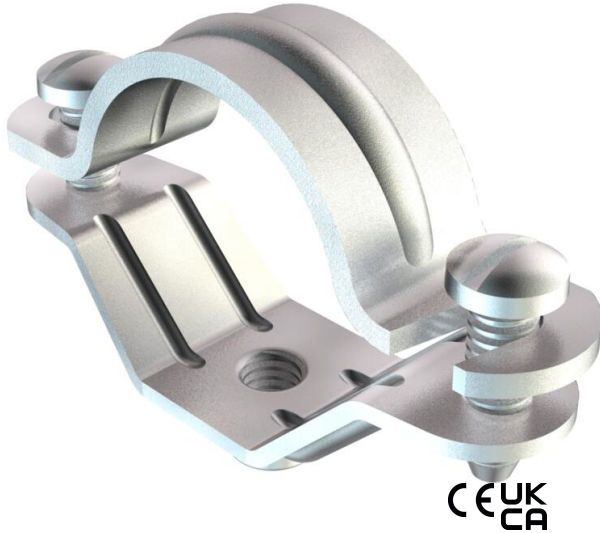

St	Steel
G	Electrogalvanized

Master data

Item number	1383299
Type	2900 M6 30-34 G
Description 1	Distance saddle
Description 2	with threaded connection M6
Manufacturer	OBO
Dimension	30-34mm
Material	Steel
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	50
Unit of quantity	Piece
Weight	4.95 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1337 kg COe / 1 Piece


Technical data sheet

Screw-in spacer clip, universal

Item number: 1383299



Dimensions

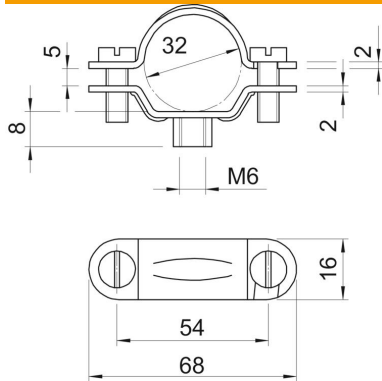

Length	68 mm
Width	16 mm
Dimension A	68 mm
Dimension B	54 mm
Dimension b	16 mm
Dimension D	32 mm
Dimension H	8 mm
Dimension t1 (mm)	2
Dimension t2 (mm)	2
Dimension x	5 mm

Technical data

Version for	Closed
Fastening type	Screw hole
Size	M32
Halogen-free	no
Plastic-covered	no
Hole size	M6 mm
Material thickness	2 mm
Bolt	M5 x 14
Clamping range D, max.	34 mm
Clamping range D, min.	30 mm
UV-resistant	yes