

Technical data sheet

Quick Clip, flame-resistant, stone grey

Item number: 2149339



Flame-resistant, flush-mounted clip to accept metric steel armoured pipes and heavy-duty insulating pipes, as well as Quick-Pipe® electrical installation pipes. Universal fastening options on walls and ceilings, both in indoor and protected outdoor areas. With slot for side alignment during mounting with wood screw or knock-in anchor. Toolless pipe mounting. Can also be arranged with OBO Multi-Quick or proQuick clip. M16 - M32 size can be screwed onto M6 thread. Recommended fastening spacing 50–60 cm, for max. extraction values F at a room temperature of 20 °C, see the table.



PP Polypropylene

Master data

Item number	2149339
Type	2955 F M63 STGR
Description 1	Quick clip
Description 2	flame-resistant
Manufacturer	OBO
Dimension	M63
Colour	Stone grey; RAL 7030
Material	Polypropylene
Smallest sales unit	20
Unit of quantity	Piece
Weight	2.203 kg
Weight unit	kg/100 pc.


Technical data sheet

Quick Clip, flame-resistant, stone grey

Item number: 2149339



Dimensions

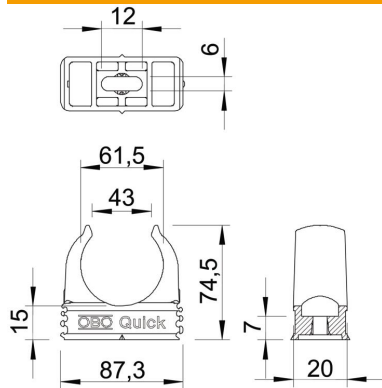

Dimension A	87.3 mm
Dimension B	20 mm
Dimension C	43 mm
Dimension D	61.5 mm
Dimension E	12 mm
Dimension F	6 mm
Dimension h	7 mm
Dimension H	74.5 mm

Technical data

Expandable	yes
Number of cables/pipes	1
Pull-out value	175 N
Fastening type	Screw hole
Flame-resistant	Acc. to VDE 0471/DIN 695 Part 2-1, test temperature 750°C
Closed	no
Halogen-free	yes
With inlay	no
Nominal size	M63
Quick clip installation	Durchgangsloch_auf_M6_Gewinde_aufschraubbar
UV-resistant	no