

Technical data sheet

Quick clip, black

Item number: 2149575



Flush-mounted clip to accept metric steel armoured pipes and heavy-duty insulating pipes, as well as Quick-Pipe® electrical installation pipes. Universal fastening options on walls and ceilings, both in indoor and protected outdoor areas. With slot for side alignment during mounting with wood screw or knock-in anchor. Toolless pipe mounting. Can also be arranged with OBO Multi-Quick or proQuick clip. M16 - M32 size can be screwed onto M6 thread. Recommended fastening spacing 50–60 cm, for max. extraction values F at a room temperature of 20 °C, see the table.



PP Polypropylene

Master data

Item number	2149575
Type	2955 M40 SW
Description 1	Quick clip
Manufacturer	OBO
Dimension	M40
Colour	Jet black; RAL 9005
Material	Polypropylene
Smallest sales unit	50
Unit of quantity	Piece
Weight	0.835 kg
Weight unit	kg/100 pc.


Technical data sheet

Quick clip, black

Item number: 2149575



Dimensions

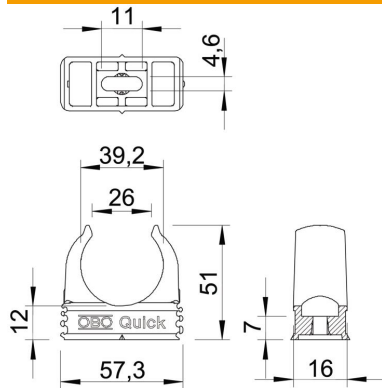

Dimension A	57.3 mm
Dimension B	16 mm
Dimension C	26 mm
Dimension D	39.2 mm
Dimension E	11 mm
Dimension F	4.6 mm
Dimension h	12 mm
Dimension H	51 mm

Technical data

Expandable	yes
Number of cables/pipes	1
Pull-out value	110 N
Fastening type	Screw hole
Closed	no
Halogen-free	yes
With inlay	no
Nominal size	M40
Quick clip installation	Durchgangsloch,_auf_M6_Gewinde_aufschraubbar
UV-resistant	no