

Technical data sheet

Base clamp clip, single

Item number: 2140128



Can be screwed onto M6 thread.



PP

Polypropylene

Master data		
Item number	2140128	
Type	2962 12 LGR	
Description 1	Base clamp	
Manufacturer	OBO	
Dimension	12mm	
Colour	Light grey; RAL 7035	
Material	Polypropylene	
Smallest sales unit	100	
Unit of quantity	Piece	
Weight	0.182 kg	
Weight unit	kg/100 pc.	
CO Footprint (GWP) Cradle-to-Gate	0,0094 kg COe / 1 Piece	


Technical data sheet

Base clamp clip, single

Item number: 2140128



Dimensions

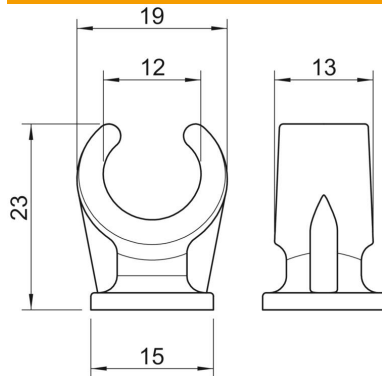

Dimension A	19 mm
Dimension B	13 mm
Dimension C	15 mm
Dimension H	23 mm

Technical data

Number of cables/pipes	1
Version for	Single-lobe
Fastening type	Threaded connection
Suitable in fire protection area	no
Size	12
Halogen-free	yes
Plastic-covered	no
Nominal diameter	11.2 mm
Clamping range D, max.	12 mm
Clamping range D, min.	12 mm
UV-resistant	no