


# Technical data sheet

## Base clamp clip, double

Item number: 2140608

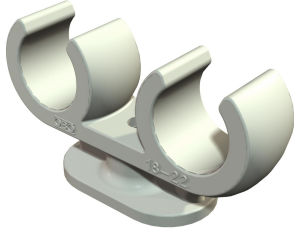

Base clamp clip, two cables 10 mm



PP

Polypropylene

### Master data

|                                   |                         |
|-----------------------------------|-------------------------|
| Item number                       | 2140608                 |
| Type                              | 2962 2X10               |
| Description 1                     | Base clamp              |
| Description 2                     | for 2 cables            |
| Manufacturer                      | OBO                     |
| Dimension                         | 10mm                    |
| Colour                            | Light grey; RAL 7035    |
| Material                          | Polypropylene           |
| Smallest sales unit               | 100                     |
| Unit of quantity                  | Piece                   |
| Weight                            | 0.283 kg                |
| Weight unit                       | kg/100 pc.              |
| CO Footprint (GWP) Cradle-to-Gate | 0,0134 kg COe / 1 Piece |


# Technical data sheet

## Base clamp clip, double

Item number: 2140608



### Dimensions

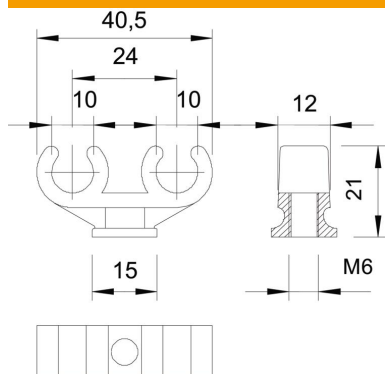

|             |         |
|-------------|---------|
| Dimension A | 40.5 mm |
| Dimension B | 12 mm   |
| Dimension C | Ø 15 mm |
| Dimension H | 21 mm   |
| Dimension L | 24 mm   |

### Technical data

|                                  |                     |
|----------------------------------|---------------------|
| Number of cables/pipes           | 2                   |
| Version for                      | Two-lobe            |
| Fastening type                   | Threaded connection |
| Suitable in fire protection area | no                  |
| Size                             | 10 + 10             |
| Halogen-free                     | yes                 |
| Plastic-covered                  | no                  |
| Nominal diameter                 | 9.6 mm              |
| Clamping range D, max.           | 10 mm               |
| Clamping range D, min.           | 10 mm               |
| UV-resistant                     | no                  |