

Technical data sheet

90° Quick pipe bend, light grey

Item number: 2154052



Fitting for plastic electrical installation pipes to create 90° bends. Suitable for Quick pipe pipes or corrugated pipes. Toolless closing and opening. Can be used in a temperature range of -25 to +60 °C.



PP

Polypropylene

Master data

Item number	2154052
Type	3000 BMS M16 LGR
Description 1	90° Quick pipe bend
Manufacturer	OBO
Dimension	M16
Colour	Light grey; RAL 7035
Material	Polypropylene
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.592 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0439 kg COe / 1 Piece


Technical data sheet

90° Quick pipe bend, light grey

Item number: 2154052



Dimensions

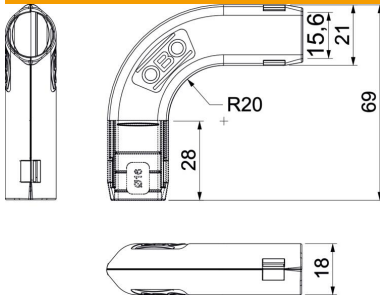

Dimension B	21.4 mm
Dimension d	15.6 mm
Dimension L	69 mm
Dimension L1	28 mm
Dimension R	20 mm

Technical data

Version for	Connector
Flexible	no
Halogen-free	yes
With inspection opening and lid	no
With sleeve	no
Brushed surface	no
Polished surface	no
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	0 °C
Angle of the bend	90 °
Two-part	yes