

# Technical data sheet

## Quick pipe connecting sleeve, light grey

Item number: 2154083



Connection sleeve for plastic electrical installation pipes to create straight connections. Suitable for Quick pipe pipes or corrugated pipes. Toolless closing and opening. Can be used in a temperature range of -25 to +60 °C.



**PP** Polypropylene

### Master data

|                                   |                              |
|-----------------------------------|------------------------------|
| Item number                       | 2154083                      |
| Type                              | 3000 MMS M20 LGR             |
| Description 1                     | Quick pipe connecting sleeve |
| Manufacturer                      | OBO                          |
| Dimension                         | M20                          |
| Colour                            | Light grey; RAL 7035         |
| Material                          | Polypropylene                |
| Smallest sales unit               | 10                           |
| Unit of quantity                  | Piece                        |
| Weight                            | 0.581 kg                     |
| Weight unit                       | kg/100 pc.                   |
| CO Footprint (GWP) Cradle-to-Gate | 0,0356 kg COe / 1 Piece      |


# Technical data sheet

Quick pipe connecting sleeve, light grey

Item number: 2154083



## Dimensions

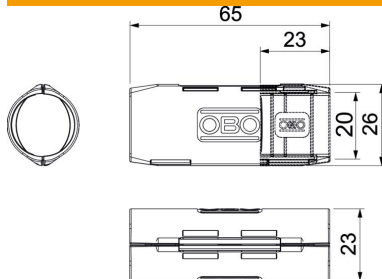

|              |       |
|--------------|-------|
| Dimension B  | 26 mm |
| Dimension d  | 20 mm |
| Dimension L  | 65 mm |
| Dimension L1 | 23 mm |

## Technical data

|                                   |       |
|-----------------------------------|-------|
| Size                              | M20   |
| Halogen-free                      | yes   |
| Polished surface                  | no    |
| Permitted temperature range, max. | 60 °C |
| Permitted temperature range, min. | 0 °C  |