

Technical data sheet

Quick pipe T piece, pure white

Item number: 2153953



Fitting for plastic electrical installation pipes to create T branches. Suitable for Quick pipe pipes or corrugated pipes. Toolless closing and opening. Can be used in a temperature range of -25 to +60 °C.



PP Polypropylene

Master data

Item number	2153953
Type	3000 TMS M20 RW
Description 1	Quick pipe T piece
Manufacturer	OBO
Dimension	M20
Colour	Pure white; RAL 9010
Material	Polypropylene
Smallest sales unit	5
Unit of quantity	Piece
Weight	1.401 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,1037 kg COe / 1 Piece


Technical data sheet

Quick pipe T piece, pure white

Item number: 2153953



Dimensions

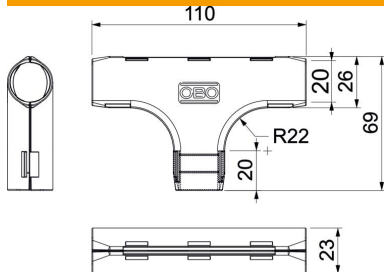

Dimension B	26 mm
Dimension B2	110 mm
Dimension d	20 mm
Dimension L	69 mm
Dimension L1	20 mm
Dimension R	22 mm

Technical data

Version for	Connector
Shape	T piece
Size	M20
Halogen-free	yes
With sleeve	no
Brushed surface	no
Polished surface	no
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	0 °C