

Technical data sheet

Quick pipe T piece, light grey

Item number: 2153843



Fitting for plastic electrical installation pipes to create T branches. Suitable for Quick pipe pipes or corrugated pipes. Toolless closing and opening. Can be used in a temperature range of -25 to +60 °C.



PP Polypropylene

Master data

Item number	2153843
Type	3000 TMS M25 LGR
Description 1	Quick pipe T piece
Manufacturer	OBO
Dimension	M25
Colour	Light grey; RAL 7035
Material	Polypropylene
Smallest sales unit	5
Unit of quantity	Piece
Weight	1.977 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1151 kg COe / 1 Piece


Technical data sheet

Quick pipe T piece, light grey

Item number: 2153843



Dimensions

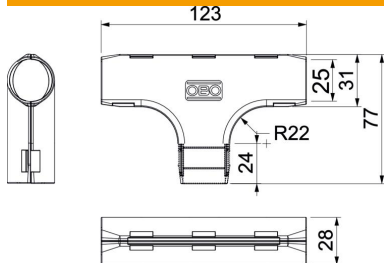

Dimension B	31 mm
Dimension B2	123 mm
Dimension d	25 mm
Dimension L	77 mm
Dimension L1	24 mm
Dimension R	22 mm

Technical data

Version for	Connector
Shape	T piece
Size	M25
Halogen-free	yes
With sleeve	no
Brushed surface	no
Polished surface	no
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	0 °C