

# Technical data sheet

## Pipe clamp

Item number: 5102154




- DIN 48818, Form D
- With  $\varnothing$  11 mm mounting hole
- 2 hexagonal bolts M8 x 20 (4 inch = M10)
- 2 hex-head nuts M8 (4 inch = M10)

St	Steel
FT	Hot-dip galvanised

### Master data

Item number	5102154
Description 1	Pipe clamp
Manufacturer	OBO
Dimension	1 1/2"
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	5
Unit of quantity	Piece
Weight	33.22 kg
Weight unit	kg/100 pc.

### Dimensions

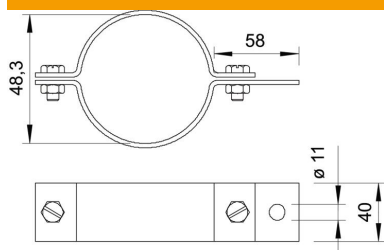

Dimension d min.	48.3 mm
------------------	---------

# Technical data sheet

## Pipe clamp

Item number: 5102154



### Technical data

Connection hole	11 mm
explosion-proof	no
for pipe	11/2
Integrated round conductor guide	no
Bimetal connector	no
Clamping range, min.	48.3 mm