


Technical data sheet

SOM clip, single

Item number: 2124173

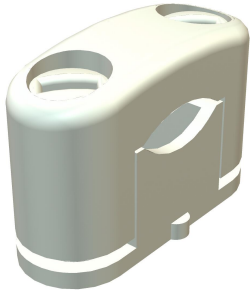

With plastic screws, so corrosion-protected, with slot for fastening with wood screws or 5 mm knock-in anchors.



PS

Polystyrene

Master data

Item number	2124173
Type	3080 LGR
Description 1	SOM clip
Manufacturer	OBO
Dimension	6-17mm
Colour	Light grey; RAL 7035
Material	Polystyrene
Smallest sales unit	50
Unit of quantity	Piece
Weight	0.926 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0282 kg COe / 1 Piece


Technical data sheet

SOM clip, single

Item number: 2124173



Dimensions

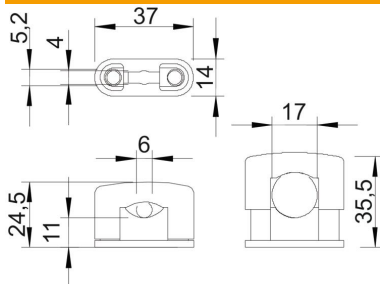

Dimension b	14 mm
Dimension b1	4 mm
Dimension b2	5.2 mm
Dimension d max.	17 mm
Dimension d min.	6 mm
Dimension H1	11 mm
Dimension H2	24.5 mm
Dimension H3	35.5 mm
Dimension L	37 mm

Technical data

Number of cables/pipes	1
Version for	Closed
Fastening type	Screw hole
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Bolt	M6 x 18
Clamping range D, max.	17 mm
Clamping range D, min.	6 mm
UV-resistant	no