

Technical data sheet

SOM clip, single

Item number: 2124254



With plastic screws, so corrosion-protected, with slot for fastening with wood screws or 5 mm knock-in anchors.



PS

Polystyrene

Master data

Item number	2124254
Type	3081 LGR
Description 1	SOM clip
Manufacturer	OBO
Dimension	15-25mm
Colour	Light grey; RAL 7035
Material	Polystyrene
Smallest sales unit	25
Unit of quantity	Piece
Weight	1.86 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0574 kg COe / 1 Piece


Technical data sheet

SOM clip, single

Item number: 2124254



Dimensions

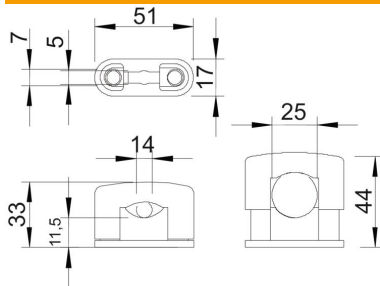

Dimension b	17 mm
Dimension b1	5 mm
Dimension b2	7 mm
Dimension d max.	25 mm
Dimension d min.	14 mm
Dimension H1	11.5 mm
Dimension H2	33 mm
Dimension H3	44 mm
Dimension L	51 mm

Technical data

Number of cables/pipes	1
Version for	Closed
Fastening type	Screw hole
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Bolt	M8 x 23
Clamping range D, max.	25 mm
Clamping range D, min.	15 mm
UV-resistant	no