

# Technical data sheet

## Steel nail G

Item number: 3354180



Hardened steel, electrogalvanised, with bead head.

|    |                   |
|----|-------------------|
| St | Steel             |
| G  | Electrogalvanized |

### Master data

|                     |                            |
|---------------------|----------------------------|
| Item number         | 3354180                    |
| Type                | 362 Z 18 G                 |
| Description 1       | Steel nail                 |
| Description 2       | hardened                   |
| Manufacturer        | OBO                        |
| Dimension           | 2x18mm                     |
| Material            | Steel                      |
| Surface             | Electrogalvanized          |
| Surface standard    | EN ISO 19598 / EN ISO 4042 |
| Smallest sales unit | 1000                       |
| Unit of quantity    | Piece                      |
| Weight              | 0.049 kg                   |
| Weight unit         | kg/100 pc.                 |


# Technical data sheet

## Steel nail G

Item number: 3354180



### Dimensions

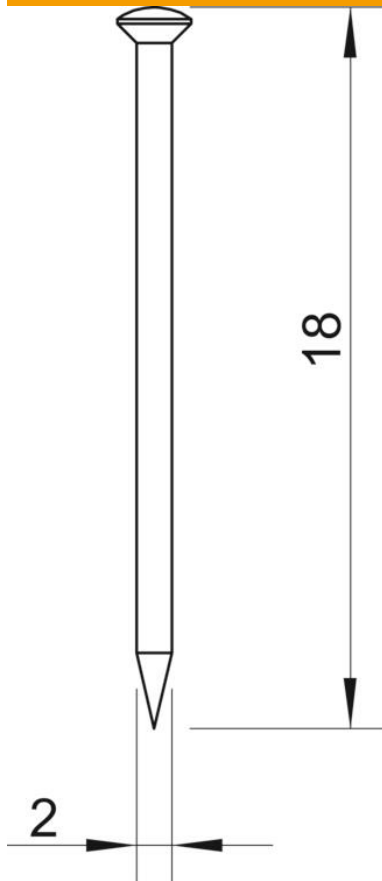

|             |       |
|-------------|-------|
| Length      | 18 mm |
| Dimension d | 2 mm  |
| Dimension L | 18 mm |

### Technical data

|                    |              |
|--------------------|--------------|
| Version for        | Nail         |
| Screw nail version | no           |
| Hardened           | yes          |
| Head shape         | Rounded head |
| Shank diameter     | 2 mm         |