

Technical data sheet

ISO nail clip 4031 10-14

Item number: 2215144



OBO makes various fastening systems available for fastening cables securely on different substrates. Starting with the adhesive clip or ISO nail clips for fastening, e.g. on wooden beams, up to the Nail-Fix for fixing in masonry slits, OBO can offer a wide range of clips for nail fastening, suitable for steel nails 2 mm.



PP Polypropylene

Master data		
Item number	2215144	
Type	4031 10-14	
Description 1	ISO nail clip	
Manufacturer	OBO	
Dimension	10-14mm	
Colour	Light grey; RAL 7035	
Material	Polypropylene	
Smallest sales unit	100	
Unit of quantity	Piece	
Weight	0.104 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,0044 kg COe / 1 Piece	


Technical data sheet

ISO nail clip 4031 10-14

Item number: 2215144



Dimensions

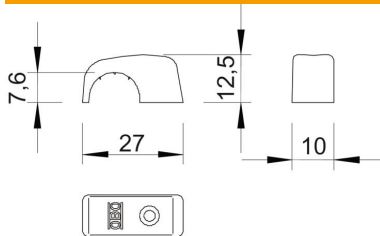

Dimension B	10 mm
Dimension H	12.5 mm
Dimension H1	7.6 mm
Dimension L	27 mm

Technical data

Double clip	no
Shape	Round (for round conductor)
for cable diameter, max.	14 mm
for cable diameter, min.	10 mm
For nail diameter	2,0
Hardened	no
Halogen-free	yes
With nail	no
Impact-resistant	no
Pipe locking	no