

Technical data sheet

ISO nail clip 4031 14-17

Item number: 2215179



OBO makes various fastening systems available for fastening cables securely on different substrates. Starting with the adhesive clip or ISO nail clips for fastening, e.g. on wooden beams, up to the Nail-Fix for fixing in masonry slits, OBO can offer a wide range of clips for nail fastening, suitable for steel nails 2 mm.



PP

Polypropylene

Master data

Item number	2215179
Type	4031 14-17
Description 1	ISO nail clip
Manufacturer	OBO
Dimension	14-17mm
Colour	Light grey; RAL 7035
Material	Polypropylene
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.155 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0068 kg COe / 1 Piece


Technical data sheet

ISO nail clip 4031 14-17

Item number: 2215179



Dimensions

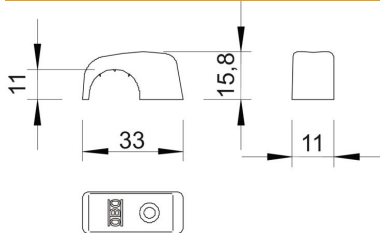

Dimension B	11 mm
Dimension H	15.8 mm
Dimension H1	11 mm
Dimension L	33 mm

Technical data

Double clip	no
Shape	Round (for round conductor)
for cable diameter, max.	17 mm
for cable diameter, min.	14 mm
For nail diameter	2,0
Hardened	no
Halogen-free	yes
With nail	no
Impact-resistant	no
Pipe locking	no