

Technical data sheet

Sprung hinged anchor

Item number: 3481662



With threaded rod and slotted brass nut, steel axle.



St	Steel
G	Electrogalvanized

Master data

Item number	3481662
Type	451 M4x95 G
Description 1	Sprung hinged anchor
Manufacturer	OBO
Dimension	M4x95mm
Material	Steel
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	50
Unit of quantity	Piece
Weight	1.7 kg
Weight unit	kg/100 pc.


Technical data sheet

Sprung hinged anchor

Item number: 3481662



Dimensions

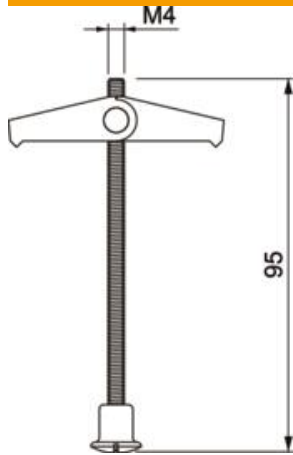

Length	90 mm
--------	-------

Technical data

Version for	With threaded shaft
Drill hole	14 mm
Drill hole diameter, min.	14 mm
Breaking load	0.2 kN
Thread	M4
Thread type	Metric
Minimum cavity depth	35 mm
With washer	no
Protection ring for ceramics	no