

Technical data sheet

Sprint screw, with Torx


Item number: 3198034



Hardened steel, electrogalvanised and Hostaflon-coated. Pan head with T bit (Allen head), sizes Ø 3 mm T10, Ø 3.5 mm T15, Ø 4 and 4.5 mm T20, Ø 5 mm T25.

The use of Sprint screws leads to considerably reduced screw-in times compared with standard screws. This noticeable advantage comes from the point with the first thread, which leads on to the double thread beyond.

Areas of use: wood, chipboard, Rigips panels, plastic anchors.

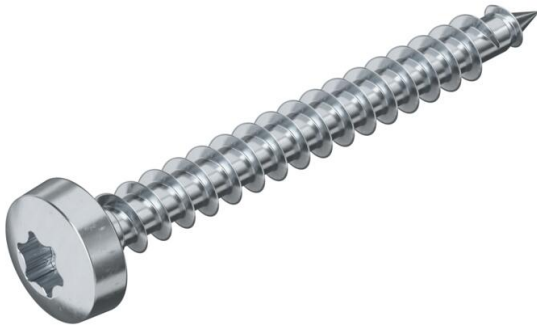

St

Steel

G

Electrogalvanized

Master data

| | |
|---------------------|----------------------------|
| Item number | 3198034 |
| Type | 4758T 4.0x25 |
| Description 1 | Sprint screw |
| Description 2 | panhead, T-drive |
| Manufacturer | OBO |
| Dimension | 4x25mm |
| Material | Steel |
| Surface | Electrogalvanized |
| Surface standard | EN ISO 19598 / EN ISO 4042 |
| Smallest sales unit | 200 |
| Unit of quantity | Piece |
| Weight | 0.187 kg |
| Weight unit | kg/100 pc. |


Technical data sheet

Sprint screw, with Torx

Item number: 3198034



Dimensions

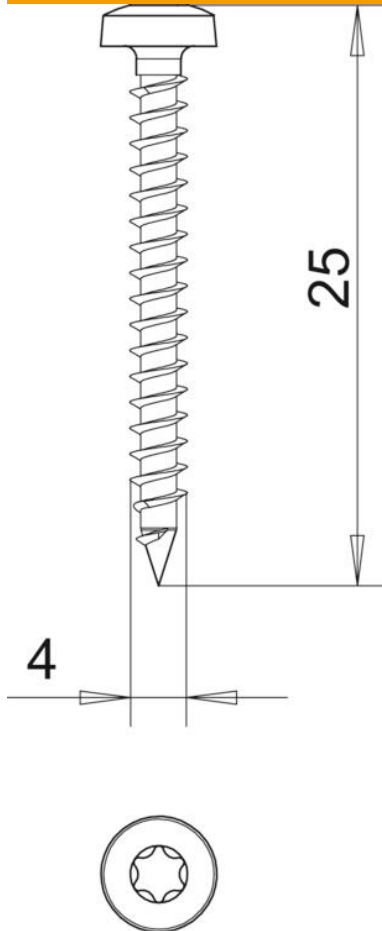

| | |
|-------------|-------|
| Length | 25 mm |
| Dimension D | 4 mm |
| Dimension L | 25 mm |

Technical data

| | |
|-----------------|---------|
| Hardened | yes |
| Head diameter | 7.5 mm |
| Head shape | Panhead |
| Screw system | Torx |
| Two-compartment | yes |