

Technical data sheet

Sprint screw, with Philips screw

Item number: 3195430



Hardened steel, electrogalvanised and Hostaflon-coated. Pan head with combined Phillips and slotted head (Pozidriv size 2 except Ø 6 mm Pozidriv size 3).

The use of Sprint screws leads to considerably reduced screw-in times compared with standard screws. This noticeable advantage comes from the point with the first thread, which leads on to the double thread beyond.

Areas of use: wood, chipboard, Rigips panels, plastic anchors.



St

Steel

G

Electrogalvanized

Master data

| | |
|---------------------|----------------------------|
| Item number | 3195430 |
| Type | 4758 4.5x30 |
| Description 1 | Sprint screw |
| Description 2 | panhead, +/- slot drive |
| Manufacturer | OBO |
| Dimension | 4,5x30mm |
| Material | Steel |
| Surface | Electrogalvanized |
| Surface standard | EN ISO 19598 / EN ISO 4042 |
| Smallest sales unit | 200 |
| Unit of quantity | Piece |
| Weight | 0.29 kg |
| Weight unit | kg/100 pc. |


Technical data sheet

Sprint screw, with Philips screw

Item number: 3195430



Dimensions

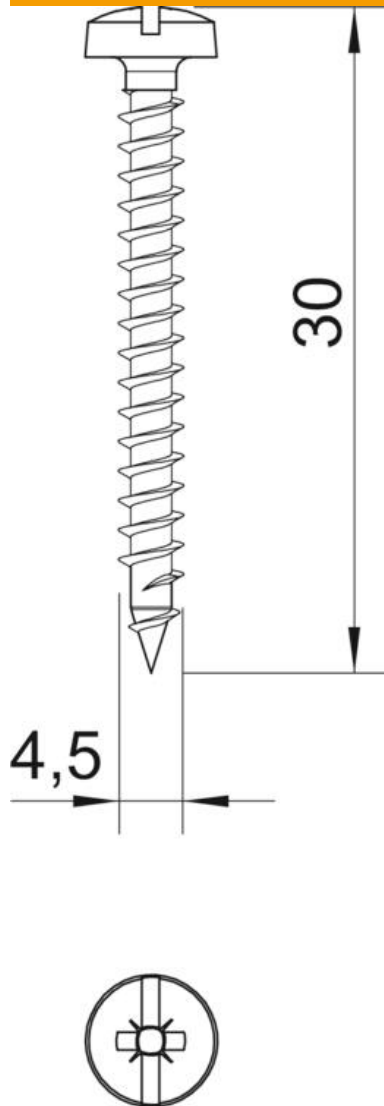

| | |
|-------------|--------|
| Length | 30 mm |
| Dimension D | 4.5 mm |
| Dimension L | 30 mm |

Technical data

| | |
|-----------------|------------------|
| Hardened | yes |
| Head diameter | 8.2 mm |
| Head shape | Panhead |
| Screw system | Combination slot |
| Two-compartment | yes |