

# Technical data sheet

## Sprint screw, with Phillips slot

Item number: 3192067



Hardened steel, electrogalvanised and Hostaflon-coated. Countersunk head with Phillips head (Pozidriv size 2 except Ø 6 mm Pozidriv size 3).

The use of Sprint screws leads to considerably reduced screw-in times compared with standard screws. This noticeable benefit is achieved by the point with the first thread, which leads onto the double thread beyond.

Areas of use: wood, chipboard, Rigips panels, plastic anchors.



St

Steel

G

Electrogalvanized

### Master data

Item number	3192067
Type	4759 3.0x30
Description 1	Sprint screw
Description 2	countersunk head, cross drive
Manufacturer	OBO
Dimension	3x30mm
Material	Steel
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	200
Unit of quantity	Piece
Weight	0.11 kg
Weight unit	kg/100 pc.


# Technical data sheet

## Sprint screw, with Philips slot

Item number: 3192067



### Dimensions

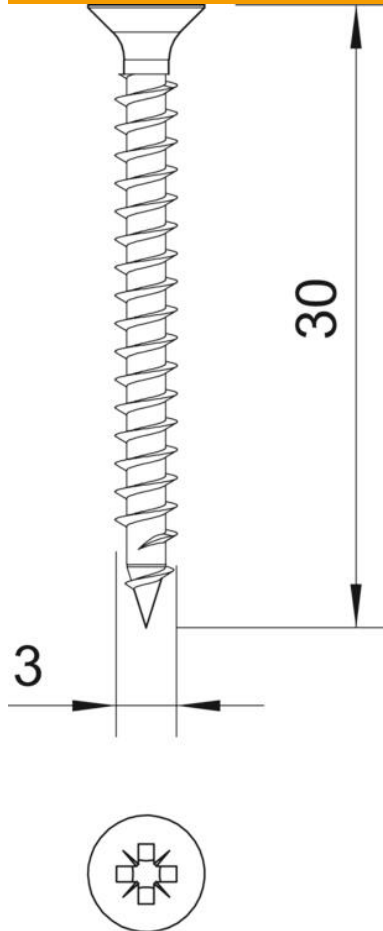

Length	30 mm
Dimension D	3 mm
Dimension L	30 mm

### Technical data

Hardened	yes
Head diameter	5.6 mm
Head shape	Countersunk head
Screw system	Pozidrive PZ