

Technical data sheet

Sprint screw, with Phillips slot

Item number: 3192113



Hardened steel, electrogalvanised and Hostaflon-coated. Countersunk head with Phillips head (Pozidriv size 2 except Ø 6 mm Pozidriv size 3).

The use of Sprint screws leads to considerably reduced screw-in times compared with standard screws. This noticeable benefit is achieved by the point with the first thread, which leads onto the double thread beyond.

Areas of use: wood, chipboard, Rigips panels, plastic anchors.



St

Steel

G

Electrogalvanized

Master data

| | |
|---------------------|-------------------------------|
| Item number | 3192113 |
| Description 1 | Sprint screw |
| Description 2 | countersunk head, cross drive |
| Manufacturer | OBO |
| Dimension | 3,5x25mm |
| Material | Steel |
| Surface | Electrogalvanized |
| Surface standard | EN ISO 19598 / EN ISO 4042 |
| Smallest sales unit | 200 |
| Unit of quantity | Piece |
| Weight | 0.105 kg |
| Weight unit | kg/100 pc. |


Technical data sheet

Sprint screw, with Philips slot

Item number: 3192113



Dimensions

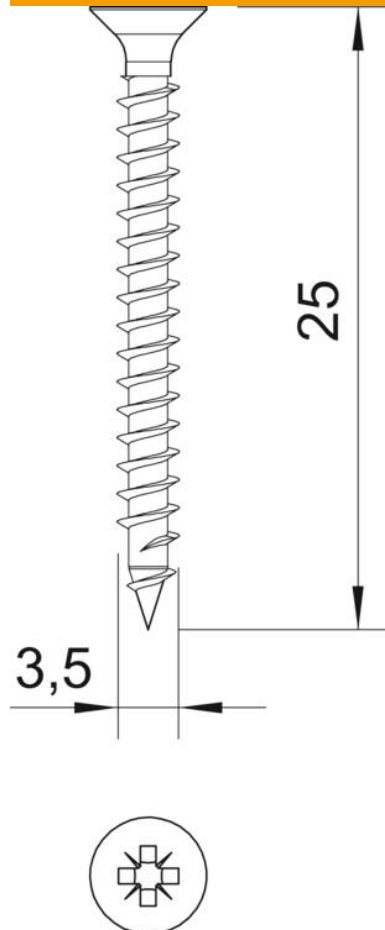

| | |
|-------------|--------|
| Length | 25 mm |
| Dimension D | 3.5 mm |
| Dimension L | 25 mm |

Technical data

| | |
|---------------|------------------|
| Hardened | yes |
| Head diameter | 6.5 mm |
| Head shape | Countersunk head |
| Screw system | Pozidrive PZ |