

Technical data sheet

Cable tie, black, UV and weather-resistant

Item number: 2331818



Cable ties are used for quick, uncomplicated fixing or bundling of cables and pipes to cable support systems or other mounting structures.




PA Polyamide

Master data

Item number	2331818
Type	565 2.5x150 SWUV
Description 1	Cable ties
Description 2	UV-resistant
Manufacturer	OBO
Dimension	2.5x150mm
Colour	Black
Material	Polyamide
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.047 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,002 kg COe / 1 Piece

Dimensions

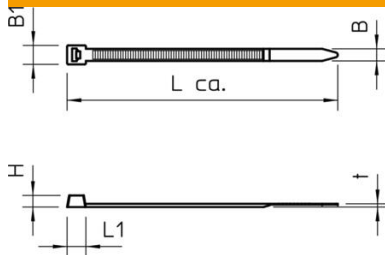

Length	150 mm
Width	2.5 mm
Height	1.3 mm
Dimension B	2.5 mm
Dimension L	150 mm
Dimension t	1.3 mm

Technical data sheet

Cable tie, black, UV and weather-resistant

Item number: 2331818



Technical data

Version for	Externally toothed
Strip closure	Plastic tongue/tab
Fastening type	Without
Labelling area	Without
Halogen-free	yes
Releasable lock	no
Max. Bundle diameter	39 mm
MIL approval	no
Mounting temperature, max.	90 °C
Mounting temperature_min.	-30 °C
Reflective	no
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-30 °C
Transparent	no
UL approval	yes
UV-resistant	yes
VG approval	no
Tensile strength	80 N