

Technical data sheet

Cable tie, white

Item number: 2331836



Cable ties are used for quick, uncomplicated fixing or bundling of cables and pipes to cable support systems or other mounting structures.



PA

Polyamide

Master data

Item number	2331836
Type	565 3.6x200 WS
Description 1	Cable ties
Manufacturer	OBO
Dimension	3,6x200mm
Colour	White
Material	Polyamide
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.104 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0041 kg COe / 1 Piece


Technical data sheet

Cable tie, white

Item number: 2331836



Dimensions

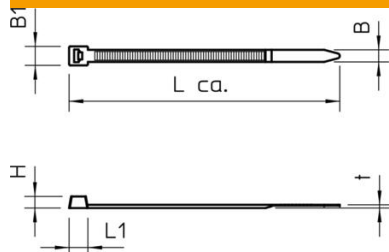

Length	200 mm
Width	3.6 mm
Height	1.4 mm
Dimension B	3.6 mm
Dimension L	200 mm
Dimension t	1.4 mm

Technical data

Version for	Externally toothed
Strip closure	Plastic tongue/tab
Fastening type	Without
Labelling area	Without
Halogen-free	yes
Releasable lock	no
Max. Bundle diameter	52 mm
MIL approval	no
Mounting temperature, max.	90 °C
Mounting temperature_min.	-30 °C
Reflective	no
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-30 °C
Transparent	no
UL approval	yes
UV-resistant	no
VG approval	no
Tensile strength	180 N