

Technical data sheet

Cable tie, black, UV and weather-resistant

Item number: 2331844



Cable ties are used for quick, uncomplicated fixing or bundling of cables and pipes to cable support systems or other mounting structures.




PA Polyamide

Master data

Item number	2331844
Type	565 3.6x290 SWUV
Description 1	Cable ties
Description 2	UV-resistant
Manufacturer	OBO
Dimension	3.6x290mm
Colour	Black
Material	Polyamide
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.14 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0056 kg COe / 1 Piece

Dimensions

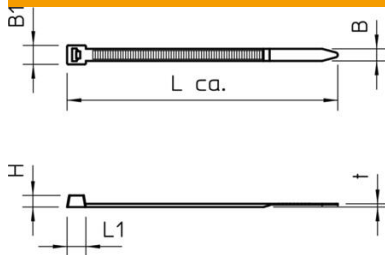

Length	290 mm
Width	3.6 mm
Height	1.4 mm
Dimension B	3.6 mm
Dimension L	290 mm
Dimension t	1.4 mm

Technical data sheet

Cable tie, black, UV and weather-resistant

Item number: 2331844



Technical data

Version for	Externally toothed
Strip closure	Plastic tongue/tab
Fastening type	Without
Labelling area	Without
Halogen-free	yes
Releasable lock	no
Max. Bundle diameter	82 mm
MIL approval	no
Mounting temperature, max.	90 °C
Mounting temperature_min.	-30 °C
Reflective	no
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-30 °C
Transparent	no
UL approval	yes
UV-resistant	yes
VG approval	no
Tensile strength	180 N