

# Technical data sheet

Cable tie, black, UV and weather-resistant

Item number: 2331880



Cable ties are used for quick, uncomplicated fixing or bundling of cables and pipes to cable support systems or other mounting structures.




PA Polyamide

## Master data

|                                   |                         |
|-----------------------------------|-------------------------|
| Item number                       | 2331880                 |
| Type                              | 565 4.8x300 SWUV        |
| Description 1                     | Cable ties              |
| Description 2                     | UV-resistant            |
| Manufacturer                      | OBO                     |
| Dimension                         | 4.8x300mm               |
| Colour                            | Black                   |
| Material                          | Polyamide               |
| Smallest sales unit               | 100                     |
| Unit of quantity                  | Piece                   |
| Weight                            | 0.201 kg                |
| Weight unit                       | kg/100 pc.              |
| CO Footprint (GWP) Cradle-to-Gate | 0,0079 kg COe / 1 Piece |

## Dimensions

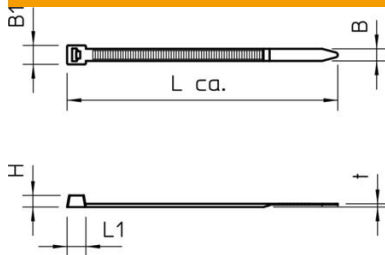

|             |        |
|-------------|--------|
| Length      | 300 mm |
| Width       | 4.8 mm |
| Height      | 1.6 mm |
| Dimension B | 4.8 mm |
| Dimension L | 300 mm |
| Dimension t | 1.5 mm |

# Technical data sheet

Cable tie, black, UV and weather-resistant

Item number: 2331880



## Technical data

|                                   |                    |
|-----------------------------------|--------------------|
| Version for                       | Externally toothed |
| Strip closure                     | Plastic tongue/tab |
| Fastening type                    | Without            |
| Labelling area                    | Without            |
| Halogen-free                      | yes                |
| Releasable lock                   | no                 |
| Max. Bundle diameter              | 83 mm              |
| MIL approval                      | no                 |
| Mounting temperature, max.        | 90 °C              |
| Mounting temperature_min.         | -30 °C             |
| Reflective                        | no                 |
| Permitted temperature range, max. | 90 °C              |
| Permitted temperature range, min. | -30 °C             |
| Transparent                       | no                 |
| UL approval                       | yes                |
| UV-resistant                      | yes                |
| VG approval                       | no                 |
| Tensile strength                  | 220 N              |