


# Technical data sheet

## Protection conductor terminal, with screw contacts, 12 terminals

Item number: 2054094

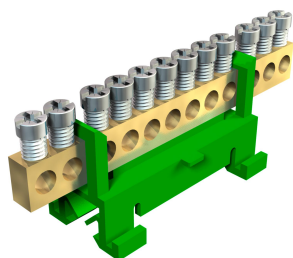

Protective conductor connection terminal with 7 terminals up to 16 mm<sup>2</sup>.

Clamping rail, brass, steel screws, electrogalvanised and transparently passivated, for snapping onto 35 x 7.5 mm hat profile rails to DIN EN 60715 (previously DIN EN 50022) (transverse) or flat rails 10 x 2–2.5 mm (lengthwise).



### Master data

Item number	2054094
Type	60 S 12x16 GN
Description 1	Protective conductor terminal
Manufacturer	OBO
Dimension	12x16mm <sup>2</sup>
Colour	Green
Material	Polyamide
Smallest sales unit	10
Unit of quantity	Piece
Weight	4.2 kg
Weight unit	kg/100 pc.


# Technical data sheet

Protection conductor terminal, with screw contacts, 12 terminals

Item number: 2054094



## Dimensions

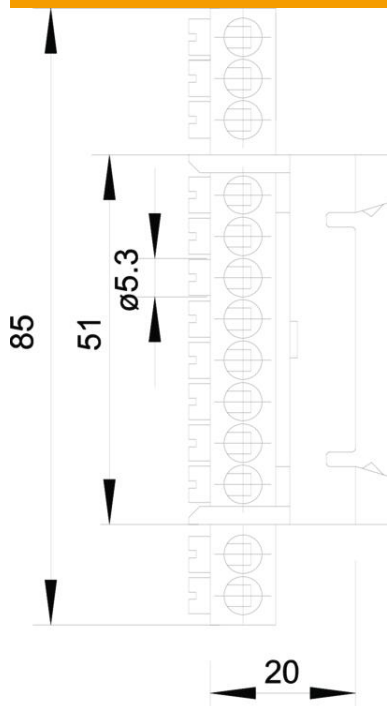

Length	85 mm
Height	20 mm

## Technical data

Closing plate required	no
No. of terminals	12
Explosion-tested version	no
Suitable for flexible conductors	no
Suitable for solid conductors	no
Suitable for multi-wire conductors	no
Mounting type	DIN rail 35 mm
Nominal cross-section, max.	16 mm <sup>2</sup>
Nominal cross-section, min.	10 mm <sup>2</sup>
Pole number	12
Cross-section	12 terminals to 16 mm <sup>2</sup> mm <sup>2</sup>