


Technical data sheet

Protection conductor terminal, with screw contacts, 7 terminals

Item number: 2054019

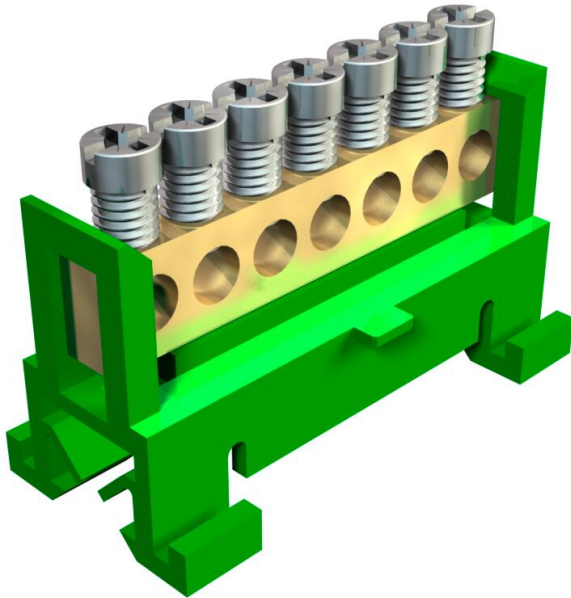

Protective conductor connection terminal with 7 terminals up to 16 mm².

Clamping rail, brass, steel screws, electrogalvanised and transparently passivated, for snapping onto 35 x 7.5 mm hat profile rails to DIN EN 60715 (previously DIN EN 50022) (transverse) or flat rails 10 x 2–2.5 mm (lengthwise).
60/N 7 and 60/S 7: with 7 terminals to 16 mm².



PA Polyamide

Master data

Item number	2054019
Type	60 S 7x16 GN
Description 1	Protective conductor terminal
Manufacturer	OBO
Dimension	7x16mm ²
Colour	Green
Material	Polyamide
Smallest sales unit	10
Unit of quantity	Piece
Weight	2.9 kg
Weight unit	kg/100 pc.


Technical data sheet

Protection conductor terminal, with screw contacts, 7 terminals

Item number: 2054019



Dimensions

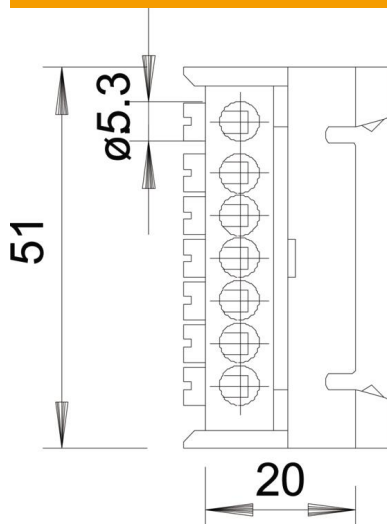

Length	51 mm
Height	20 mm

Technical data

Closing plate required	no
No. of terminals	7
Explosion-tested version	no
Suitable for flexible conductors	no
Suitable for solid conductors	no
Suitable for multi-wire conductors	no
Mounting type	DIN rail 35 mm
Nominal cross-section, max.	16 mm ²
Nominal cross-section, min.	10 mm ²
Pole number	7
Cross-section	7 terminals to 16 mm ² mm ²