




# Technical data sheet

## Universal plug-in terminal, 2-pole


Item number: 2054450



### Dimensions

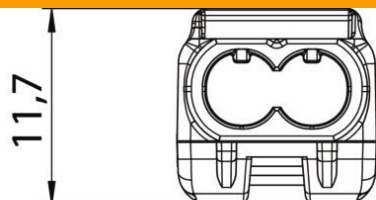

|        |         |
|--------|---------|
| Length | 11.9 mm |
| Width  | 21 mm   |
| Height | 11.7 mm |

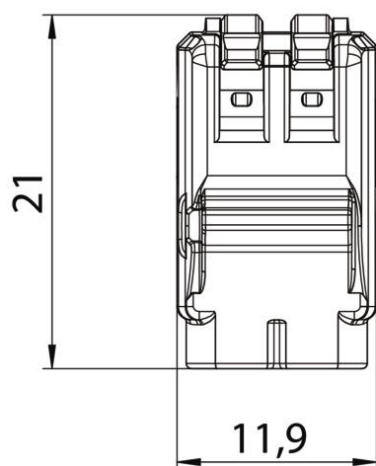

# Technical data sheet

## Universal plug-in terminal, 2-pole

Item number: 2054450



### Technical data

|                                                        |                                                                                          |
|--------------------------------------------------------|------------------------------------------------------------------------------------------|
| Connectable conductor cross-section, single-wire, max. | 2.5 mm <sup>2</sup>                                                                      |
| Connectable conductor cross-section, single-wire, min. | 0.2 mm <sup>2</sup>                                                                      |
| Connectable conductor cross-section, multi-wire, max.  | 2.5 mm <sup>2</sup>                                                                      |
| Connectable conductor cross-section, multi-wire, min.  | 0.2 mm <sup>2</sup>                                                                      |
| No. of terminals                                       | 2                                                                                        |
| Flame-resistant                                        | Acc. to VDE 0471/DIN 695 Part 2-1, test temperature 850°C                                |
| Suitable for flexible conductors                       | yes                                                                                      |
| Suitable for solid conductors                          | yes                                                                                      |
| Suitable for multi-wire conductors                     | yes                                                                                      |
| Insulation material                                    | Thermoplast                                                                              |
| With actuating levers                                  | yes                                                                                      |
| Nominal cross-section, max.                            | 2.5 mm <sup>2</sup>                                                                      |
| Nominal cross-section, min.                            | 0.2 mm <sup>2</sup>                                                                      |
| Nominal voltage                                        | 450 V                                                                                    |
| Nominal current                                        | 24 A                                                                                     |
| Pole number                                            | 1                                                                                        |
| Cross-section                                          | 2 x 0.2 - 2.5 mm <sup>2</sup> multi-wire cables / single-wire conductors mm <sup>2</sup> |
| Permitted temperature range, max.                      | 85 °C                                                                                    |
| Permitted temperature range, min.                      | -5 °C                                                                                    |